
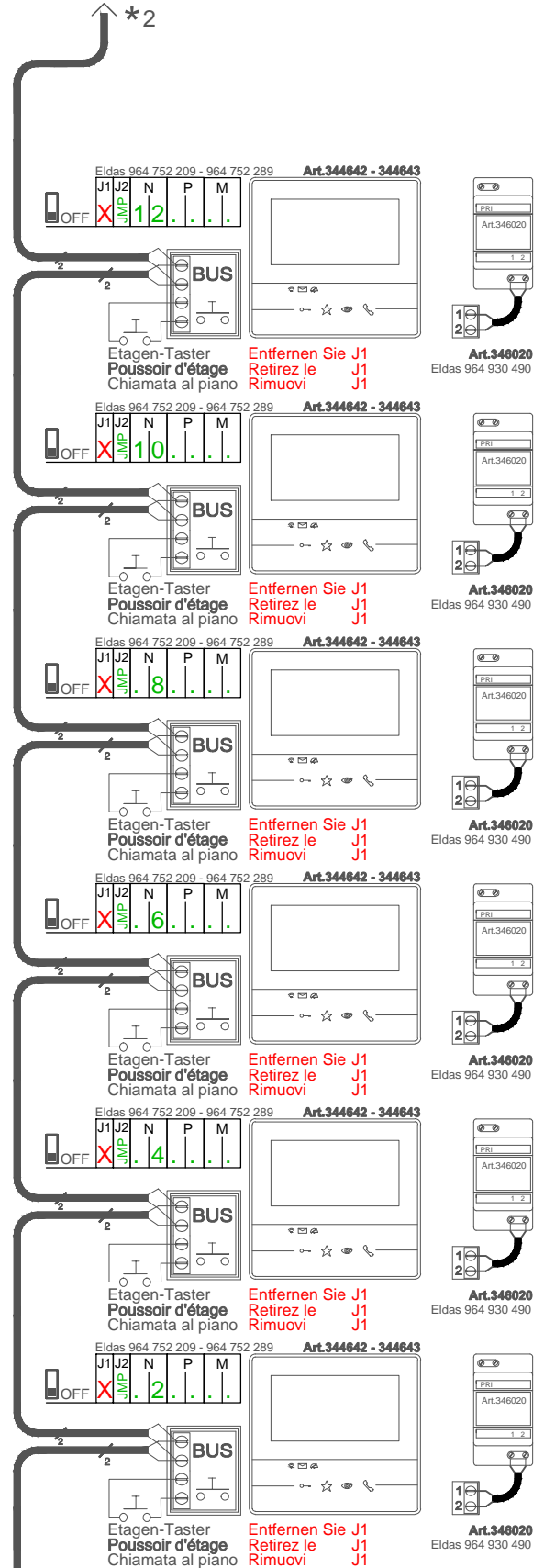


**\* 1-4 (Strang / Colonne montante / Montante)**  
**X (Entfernen Sie J1 / Retirez le J1 / Rimuovi J1)**

**Info: Verdrillte kabel verwenden / Utiliser des câbles torsadés**  
**Utilizzare cavi twistati Art.336904 - Eldas 101 282 009**

21 INT 1.2/00

41 INT 1.2/06

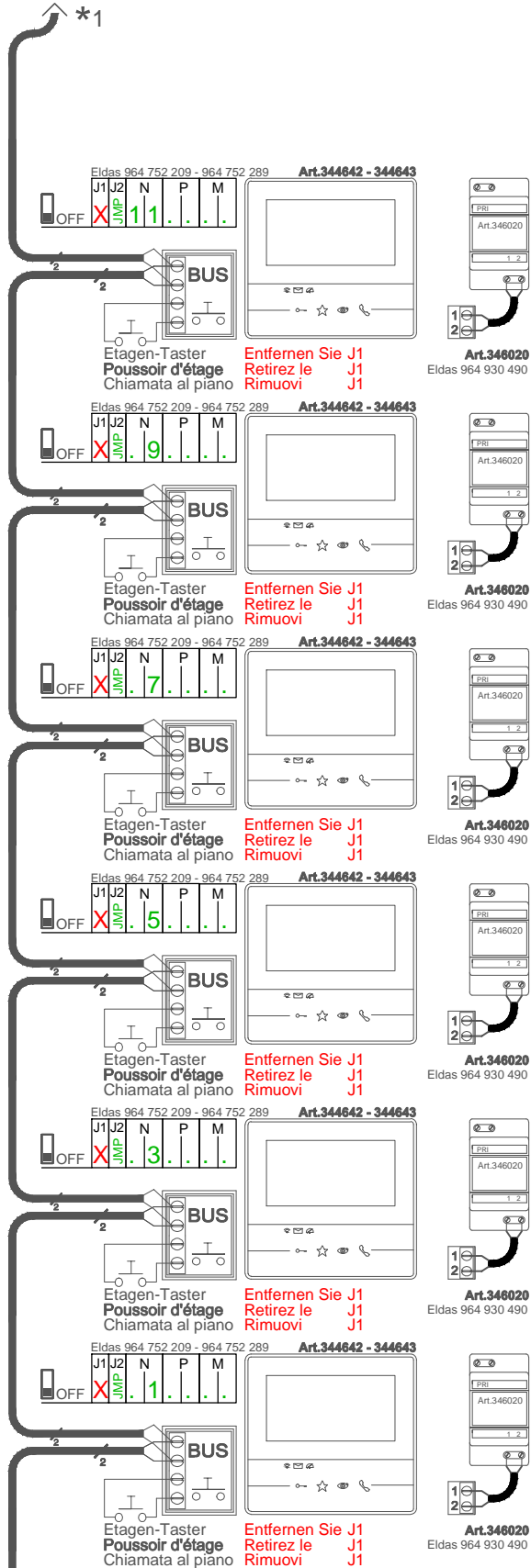

21 TAB 1.1/00



41 TAB 1.1/06

\* 1-4 (Strang / Colonne montante / Montante)  
 X (Entfernen Sie J1 / Retirez le J1 / Rimuovi J1)

Info: Verdrillte kabel verwenden / Utiliser des câbles torsadés  
 Utilizzare cavi twistati Art.336904 - Eldas 101 282 009

21 INT 1.3/00

41 INT 1.3/06

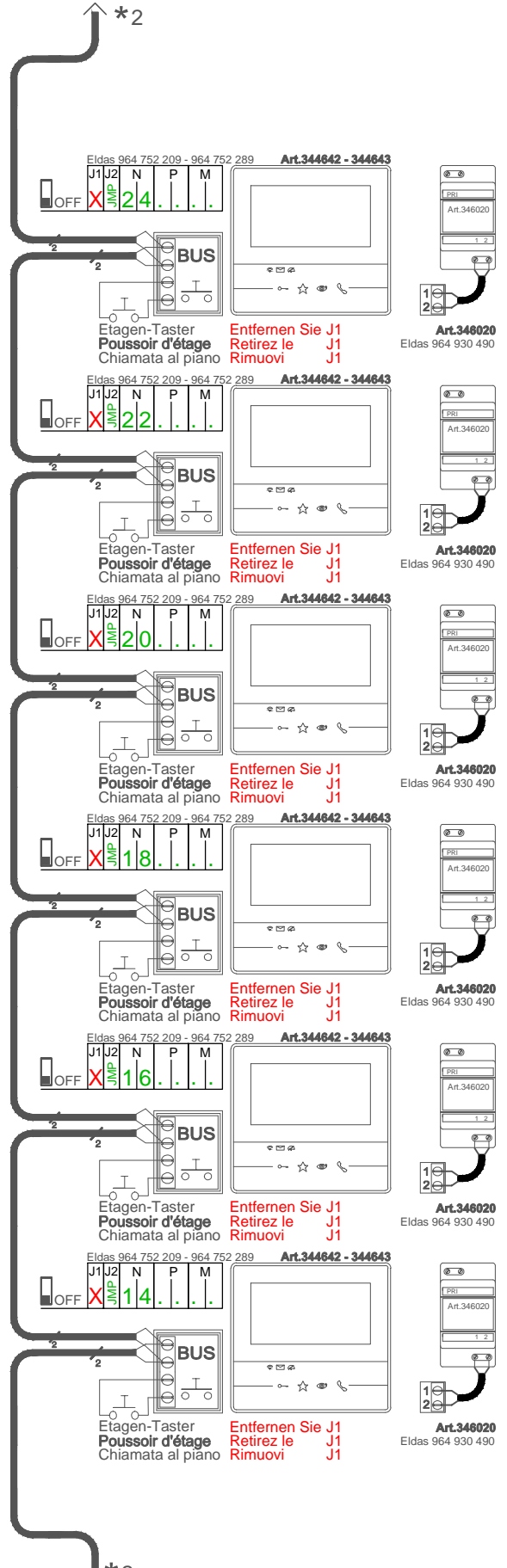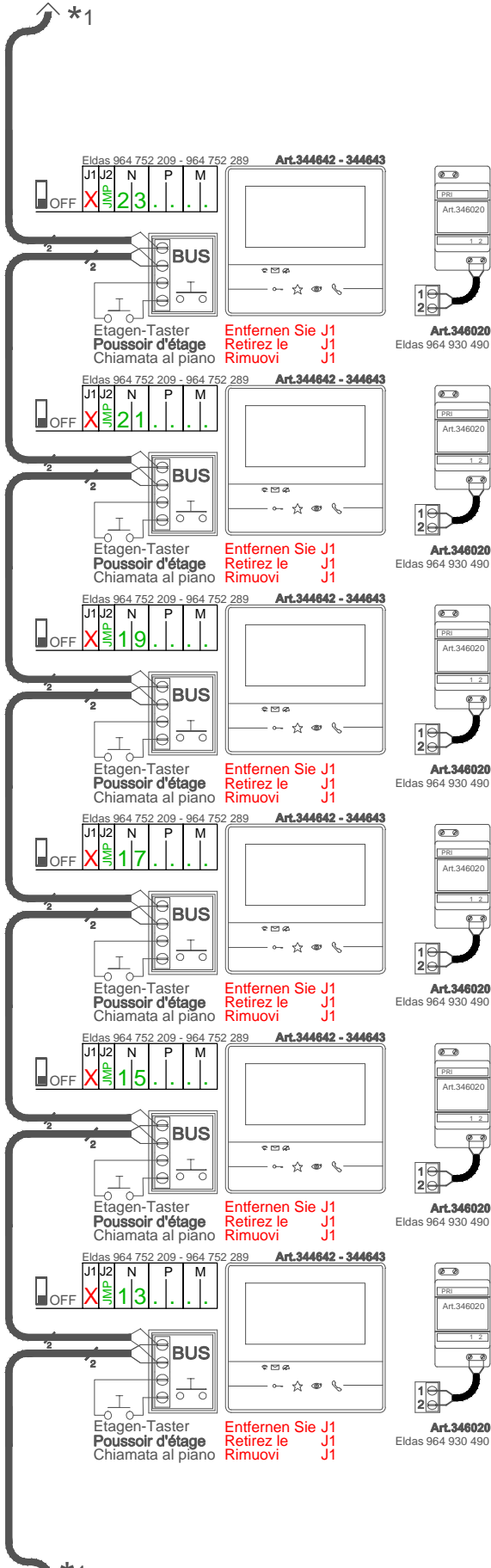


21 INT 1.1/00

41 INT 1.1/06

**\* 1-4 (Strang / Colonne montante / Montante)**  
**X (Entfernen Sie J1 / Retirez le J1 / Rimuovi J1)**


Info: **Verdrillte kabel verwenden / Utiliser des câbles torsadés**  
 Utilizzare cavi twistati Art.336904 - Eldas 101 282 009

21 INT 1.4/00

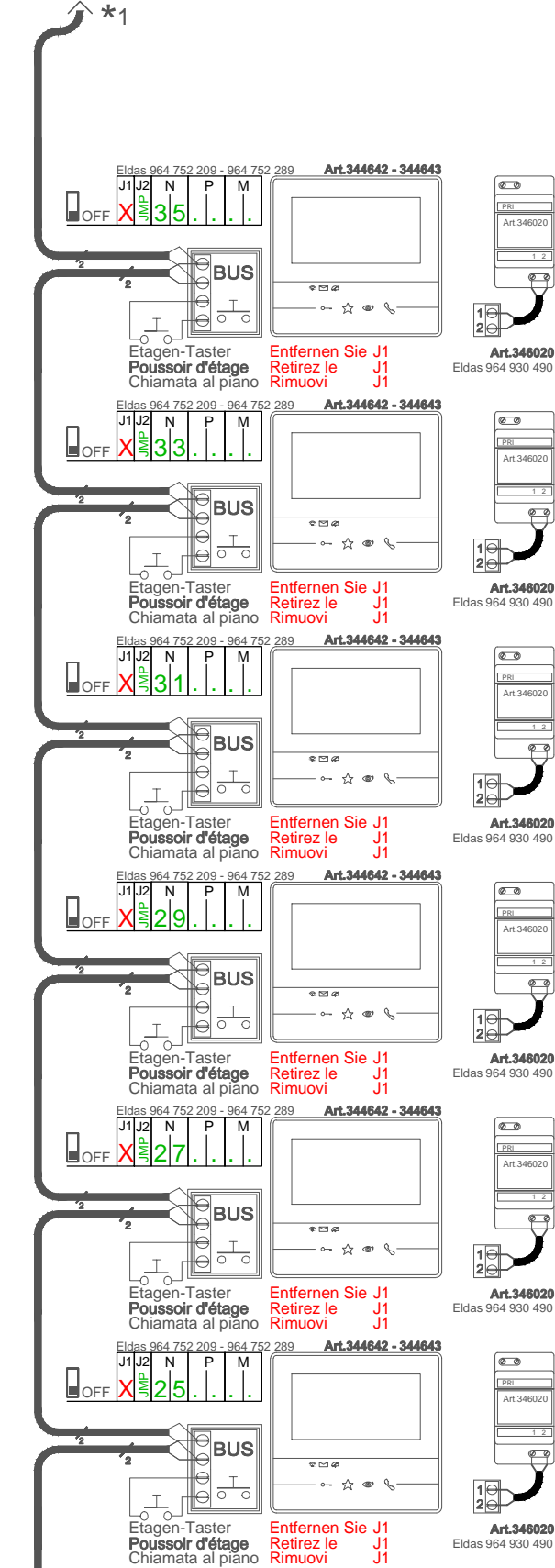

21 INT 1.2/00

41 INT 1.2/06

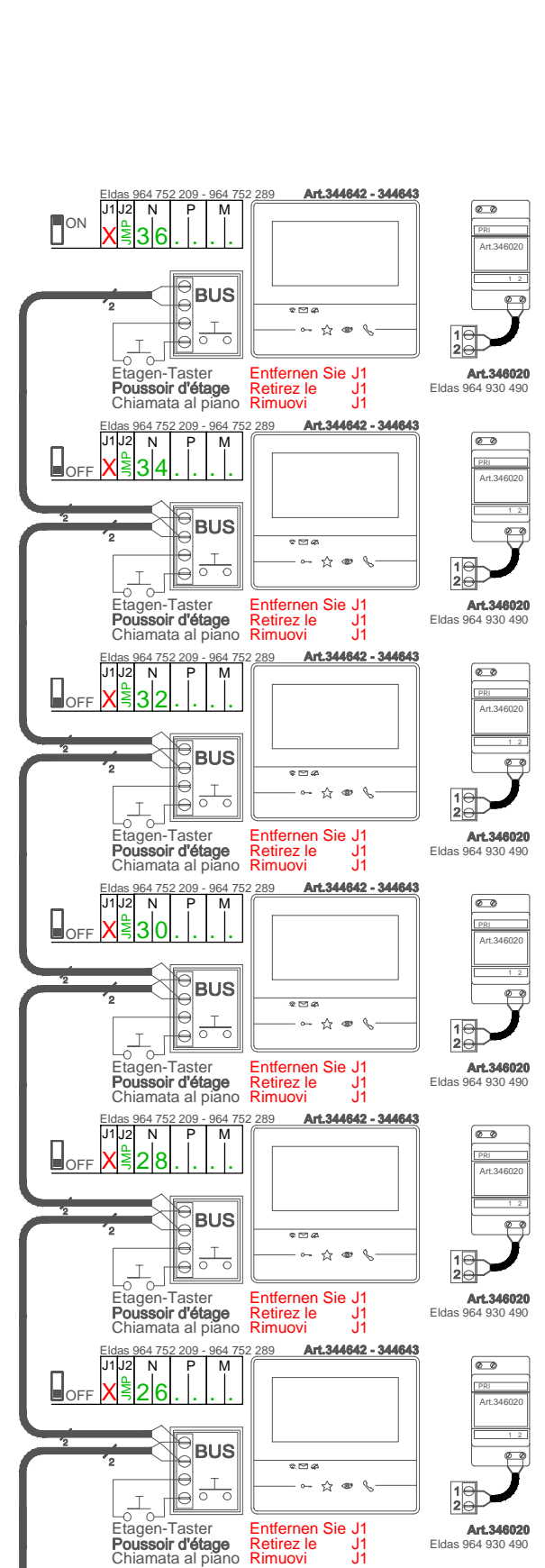

**\* 1-4 (Strang / Colonne montante / Montante)**  
**X (Entfernen Sie J1 / Retirez le J1 / Rimuovi J1)**

Info: **Verdrillte kabel verwenden / Utiliser des câbles torsadés**  
 Utilizzare cavi twistati Art.336904 - Eldas 101 282 009

